




WNT5A Antibody [3D10]

CATALOG NUMBER: 51-302

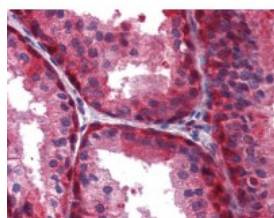

Immunohistochemistry of human prostate tissue stained using WNT5A Monoclonal Antibody.

Specifications

SPECIES REACTIVITY:	Human
TESTED APPLICATIONS:	ELISA, IHC, WB
APPLICATIONS:	WNT5A antibody can be used in ELISA starting at 1:000 - 1:1000, and immunohistochemistry starting at 10 ug/mL.
USER NOTE:	Optimal dilutions for each application to be determined by the researcher.
IMMUNOGEN:	Recombinant fragment of Wnt5A
HOST SPECIES:	Mouse

Properties

PURIFICATION:	Ascites
PHYSICAL STATE:	Liquid
BUFFER:	0.03% sodium azide
STORAGE CONDITIONS:	WNT5A antibody can be stored short term 4 °C. For long term storage aliquot and store at -20 °C. As with all antibodies avoid freeze/thaw cycles.
CLONALITY:	Monoclonal
ISOTYPE:	IgG1
CONJUGATE:	Unconjugated

Additional Info

ALTERNATE NAMES:	WNT5A, HWNT5A, Protein Wnt-5a, WNT-5A protein
ACCESSION NO.:	P41221
PROTEIN GI NO.:	212276478
OFFICIAL SYMBOL:	WNT5A
GENE ID:	7474

Background

